


SS35H-35047

Aliases (UAL35H35047000)

Not for New Design

KEMET, SS35V/35H, AC Line Filters, Common Mode, 4.7 mH

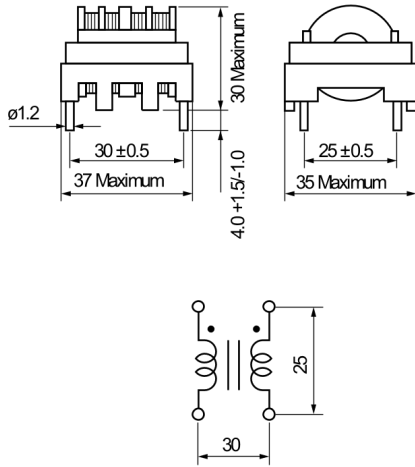

General Information

Series	SS35V/35H
Style	Through-Hole
RoHS	Yes
Miscellaneous	Inductance Measurement Condition: 1kHz 1V KC530.

Specifications

Voltage AC	250 VAC
Inductance	4.7 mH
Current	3.5 A
Temperature Range	-25/+120°C
DC Resistance	0.1 Ohms

Dimensions

L	37mm MAX
T	35mm MAX
H	30mm MAX
LL	4mm +1.5/-1mm
S	30mm +/-0.5mm
S1	25mm +/-0.5mm

Packaging Specifications

Typical Component Weight	54 g
--------------------------	------