


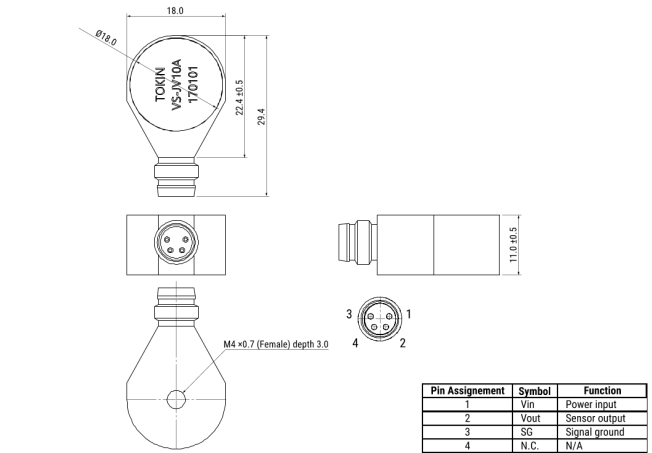

Click [here](#) for the 3D model.

Dimensions	
D	18mm NOM
L	29.4mm NOM
L2	22.4mm +/-0.5mm
T	11mm +/-0.5mm

Packaging Specifications	
Packaging	Bulk, Box
Packaging Quantity	10
Typical Component Weight	19 g

General Information	
Series	VS-J
Type	Vibration
Style	Metal Sealed
Description	Vibration Sensor
Features	Proprietary Piezo Ceramic Material, Built-in Amplifier, Detachable Cable
RoHS	With Exemptions
REACH	SVHC (PZT - CAS 12626-81-2)
SCIP Number	640fe643-8c06-4489-831d-d384ddba7405

Specifications	
Temperature Range	-25/+85°C
Power Supply Voltage	3.2 - 5.5 VDC
Protection	IP67 and oil-resistant
Sensitivity	10 mV/m/s²
Frequency Range	10 - 15,000 Hz
Measuring Range	+/-100 m/s²